


KFB12-B-PP-AS

Linear Ball Bearing and Housing Unit

Linear ball bearing and housing unit; with flange, sealed, greased, with relubrication facility; corrosion-resistant design possible

Technical information

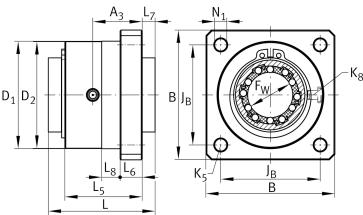

Your current product variant

Size code	12
Seal	PP
Relubrication feature	AS

Technical data

	5	Ball rows
≈m	0,08 kg	Weight

Main Dimensions & Performance Data

F _W	12 mm	Diameter of ball complement
Tol F _W	+ 0,008 mm	Upper tolerance
L	32 mm	Length
B	40 mm	Width
C	540 N	Load capacity dyn. C
C ₀	385 N	Load capacity stat. C0



Mounting dimensions

L 5	22 mm	
L 6	6 mm	Thickness
L 7	4,2 mm	
A 3	11,5 mm	
N 1	5,5 mm	Diameter
K 5	M5	
D 1	31,5 mm	Diameter
Tol D 1	+ 0,2 mm	Upper tolerance
D 2	32 mm	Diameter
Tol D 2	g7	Upper tolerance
J B	30 mm	
L 8	10 mm	
K 8	NIPD3	Lubrication nipple