





KGHK06-B-PP-AS

Linear Ball Bearing and Housing Unit

Linear ball bearing and housing unit; sealed, greased, with relubrication facility; corrosion-resistant design possible

Technical information

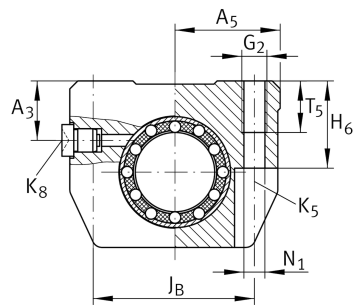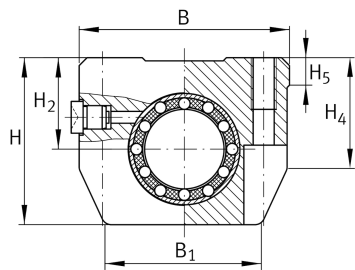


Your current product variant

Size code	06
Version	B
Seal	PP
Relubrication feature	AS

Main Dimensions & Performance Data

F _W	6 mm	Diameter of ball complement
H	27 mm	Height
L	22,2 mm	Length
B	32 mm	Width
C	340 N	Dynamic load rating
C ₀	240 N	Basic static load capacity
≈m	30 g	Weight

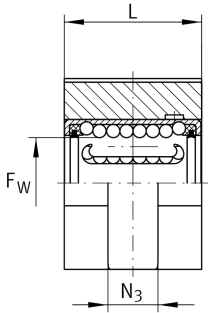

Mounting dimensions

J B	23 mm	
Tol J B	+ 0,15 mm	Upper tolerance
Tol J B	- 0,15 mm	Lower tolerance
B 1	25 mm	
A 5	16 mm	
H 2	13 mm	Center height
Tol H 2	+ 0,01 mm	Upper tolerance
Tol H 2	- 0,014 mm	Lower tolerance
H 4	20,6 mm	Mounting Dimension
H 5	5 mm	
T 5	9 mm	
H 6	13 mm	Mounting Dimension
A 3	9 mm	
G 2	M4	
N 1	3,4 mm	
N 3	7 mm	
K 5	M3	
K 8	NIPA1	Lubrication nipple