


KTB20-B-PP-AS

Linear Ball Bearing and Housing Unit

Linear ball bearing and housing unit; sealed, greased, with relubrication facility; corrosion-resistant design possible

Technical information

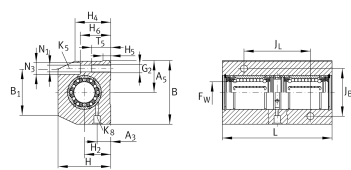

Your current product variant

Size code	20
Seal	PP
Relubrication	AS

Main Dimensions & Performance Data

F _W	20 mm	Diameter of ball complement
Tol F _W	+ 0,009 mm	Upper tolerance
Tol F _W	- 0,001 mm	Lower tolerance
H	50 mm	Height
L	104 mm	Length
B	60 mm	Width
C	2.550 N	Load capacity dyn. C
C ₀	2.450 N	Load capacity stat. C0
m	0,745 kg	Weight



Mounting dimensions

J _B	45 mm	
Tol J _B	+ 0,15 mm	Upper tolerance
Tol J _B	- 0,15 mm	Lower tolerance
A ₅	30 mm	Mounting Dimension
B ₁	44 mm	
J _L	55 mm	
Tol J _L	+ 0,15 mm	Upper tolerance
Tol J _L	- 0,15 mm	Lower tolerance
H ₂	25 mm	Center height
Tol H ₂	+ 0,015 mm	Upper tolerance
Tol H ₂	- 0,015 mm	Lower tolerance
H ₄	33 mm	
A ₃	13 mm	
H ₅	7,4 mm	
T ₅	18 mm	
H ₆	37 mm	
N ₁	6,4 mm	
N ₃	11 mm	
G ₂	M8	Thread size
K ₈	NIPA2	Lubrication nipple
K ₅	M6	Screw ISO 4762