


KFB20-B-PP-AS

Linear Ball Bearing and Housing Unit

Linear ball bearing and housing unit; with flange, sealed, greased, with relubrication facility; corrosion-resistant design possible

Technical information

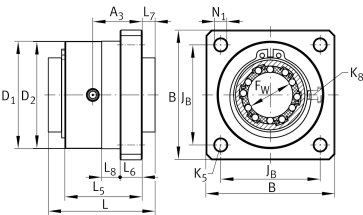

Your current product variant

Size code	20
Seal	PP
Relubrication	AS

Technical data

	6	Ball rows
≈m	0,22 kg	Weight

Main Dimensions & Performance Data

F _W	20 mm	Diameter of ball complement
Tol F _W	+ 0,009 mm	Upper tolerance
Tol F _W	- 0,001 mm	Lower tolerance
L	45 mm	Length
B	60 mm	Width
C	1.570 N	Load capacity dyn. C
C ₀	1.230 N	Load capacity stat. C0



Mounting dimensions

L 5	30 mm	
L 6	10 mm	Thickness
L 7	6,7 mm	
A 3	15,8 mm	
N 1	6,6 mm	Diameter
K 5	M6	
D 1	45,5 mm	Diameter
Tol D 1	+ 0,2 mm	Upper tolerance
D 2	46 mm	Diameter
Tol D 2	g7	Upper tolerance
J B	42 mm	
L 8	10 mm	
K 8	NIPD3	Lubrication nipple