
**PABO40-PP-AS**

Linear plain bearing

Linear plain bearing; open design, sealed on all sides, with relubrication facility

Technical information

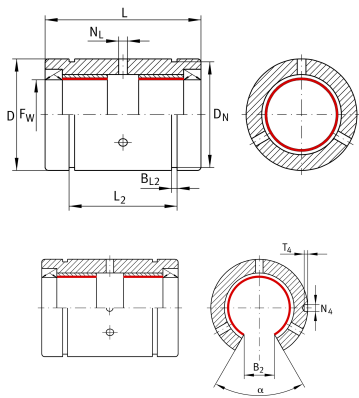

Your current product variant

Size code	40
Seal	PP
Relubrication	AS

Main Dimensions & Performance Data

F _W	40 mm	Diameter of ball complement
D	62 mm	Outer diameter
L	80 mm	Length
Tol L	h12	Tolerance
C ₀	600.000 N	Load capacity stat. C0
≈m	0,36 kg	Weight



Mounting dimensions

L 2	60,3 mm	Mounting Dimension
Tol L 2	H13	Tolerance
B L2	2,15 mm	
Tol B L2	H13	Tolerance
D N	59 mm	
B 2	18,2 mm	
T 4	1,5 mm	
N 4	3 mm	
N L	3 mm	
Tol N L	H13	Tolerance
a	54 °	Angle