



IMAGE
COMING SOON





KGHK20-B-PP-AS

Linear Ball Bearing and Housing Unit

Linear ball bearing and housing unit; sealed, greased, with relubrication facility; corrosion-resistant design possible

Technical information

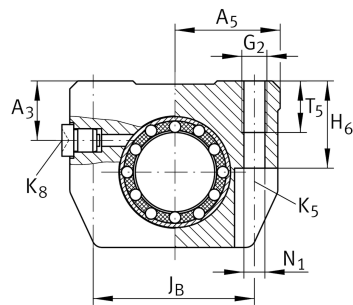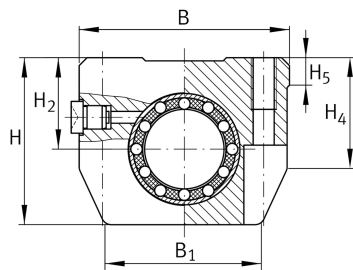


Your current product variant

Size code	20
Version	B
Seal	PP
Relubrication	AS

Main Dimensions & Performance Data

F _W	20 mm	Diameter of ball complement
H	42,5 mm	Height
L	30,2 mm	Length
B	53 mm	Width
C	1.110 N	Dynamic load rating
C ₀	790 N	Basic static load capacity
≈m	0,145 kg	Weight

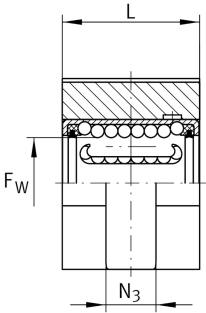

Mounting dimensions

J B	40 mm	
Tol J B	+ 0,15 mm	Upper tolerance
Tol J B	- 0,15 mm	Lower tolerance
B 1	40 mm	
A 5	26,5 mm	
H 2	23 mm	Center height
Tol H 2	+ 0,01 mm	Upper tolerance
Tol H 2	- 0,014 mm	Lower tolerance
H 4	29,8 mm	Mounting Dimension
H 5	7,4 mm	
T 5	13 mm	
H 6	22 mm	Mounting Dimension
A 3	15 mm	
G 2	M6	
N 1	5,3 mm	
N 3	11 mm	
K 5	M5	
K 8	NIPA2	Lubrication nipple