


**PAB16-PP-AS**

Linear plain bearing

Linear plain bearing; sealed on all sides, with relubrication facility

Technical information

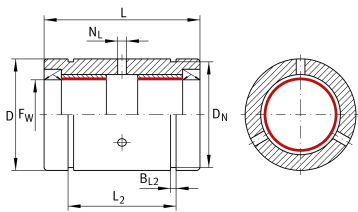

Your current product variant

Size code	16
Seal	PP
Relubrication	AS

Main Dimensions & Performance Data

F_W	16 mm	Diameter of ball complement
D	26 mm	Outer diameter
Tol D	h7	Tolerance
L	36 mm	Length
Tol L	h12	Tolerance
C_0	96.000 N	Load capacity stat. C0
$\approx m$	35 g	Weight

Mounting dimensions

L_2	24,6 mm	Mounting Dimension
Tol L_2	H13	Tolerance
B_{L2}	1,3 mm	
Tol B_{L2}	H13	Tolerance
D_N	24,9 mm	
N_L	2,5 mm	
Tol N_L	H13	Tolerance