


PAGBAO12-PP-AS

Linear plain bearing and housing unit

Linear plain bearing and housing unit; open design, sealed on all sides, with relubrication facility

Technical information

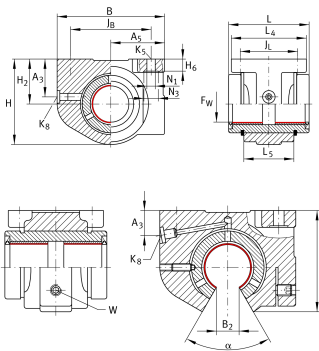

Your current product variant

Size code	12
Seal	PP
Relubrication	AS

Main Dimensions & Performance Data

F_W	12 mm	Diameter of ball complement
H	30,5 mm	Height
L	32 mm	Length
Tol L	h12	Tolerance
B	42 mm	Width
$\approx m$	60 g	Weight



Mounting dimensions

J _B	32 mm	
Tol J _B	+ 0,15 mm	Upper tolerance
Tol J _B	- 0,15 mm	Lower tolerance
A ₅	21 mm	
B ₂	7,6 mm	
L ₄	32 mm	
L ₅	20 mm	
J _L	23 mm	
Tol J _L	+ 0,15 mm	Upper tolerance
Tol J _L	- 0,15 mm	Lower tolerance
H ₂	18 mm	Center height
A ₃	7,8 mm	
H ₆	4,8 mm	
Tol H ₆	- 0,5 mm	Tolerance
N ₁	4,7 mm	Mounting Dimension
N ₃	8 mm	Mounting Dimension
K ₅	M4	
K ₈	NIPA1	Lubrication nipple
W	2 mm	Width across flats
M W _{max}	1 Nm	Max. tightening torque
α	78 °	Angle